

SEL-C953 Coaxial Cable for IRIG-B Distribution

RG-58A/U coaxial cable with BNC male connectors on both ends⁽¹⁾

Part Number:

| | | | | | | | |
|---|---|---|---|---|--|--|--|
| C | 9 | 5 | 3 | - | | | |
|---|---|---|---|---|--|--|--|

Length

Specify length—max length 130 feet (demodulated) and 500 feet (modulated) Enter length in feet with leading zeros. (Example: 5 feet = 005)


| | | | | | | | |
|--|--|--|--|--|--|--|--|
| | | | | | | | |
|--|--|--|--|--|--|--|--|

Accessories

| | | | | | | | | | |
|--|---|---|---|---|---|---|---|---|---|
| BNC Tee, Female, Male, Female (equipment mount)* | 2 | 4 | 0 | - | 1 | 7 | 9 | 9 | |
| BNC Tee, Female, Female, Male (equipment mount)* | 2 | 4 | 0 | - | 1 | 8 | 0 | 1 | |
| BNC Tee, Female, Female, Female (in-line, 3-way splice)* | 2 | 4 | 0 | - | 1 | 8 | 0 | 2 | |
| BNC terminator, 50 ohm* | 2 | 4 | 0 | - | 1 | 8 | 0 | 0 | |
| Wire-lead terminator, 50 ohm* | 9 | 1 | 5 | 9 | 0 | 0 | 0 | 3 | 6 |

* Additional Cost

⁽¹⁾ To verify your cable application, use the Cable Selector at <https://www.selinc.com/CableSelector/>.

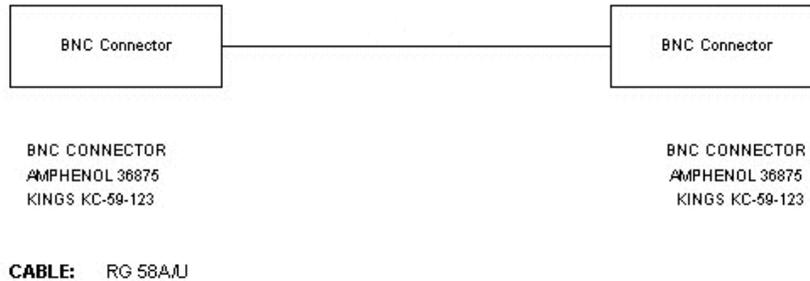

Making Electric Power Safer, More Reliable, and More Economical®

SEL SCHWEITZER ENGINEERING LABORATORIES, INC.

2350 NE Hopkins Court - Pullman, WA 99163 USA
Phone: +1.509.332.1890 - Fax: +1.509.332.7990